

# -I<sub>p</sub> vs V<sub>cc</sub>


(P0\_0-P0\_7,P1\_0-P1\_7,P2\_0-P2\_7,P3\_0,P3\_1,  
P3\_3-P3\_5,P3\_7,P4\_3-P4\_5,P6\_0-P6\_7)

Prepared on Oct. 20, 2006

R5F21248SNFP (Topr=-20 to 85degrees C)  
R5F21248SDFP (Topr=-40 to 85degrees C)  
Pull up MOS=on

— 85degreesC  
— -40degreesC

— 25degreesC

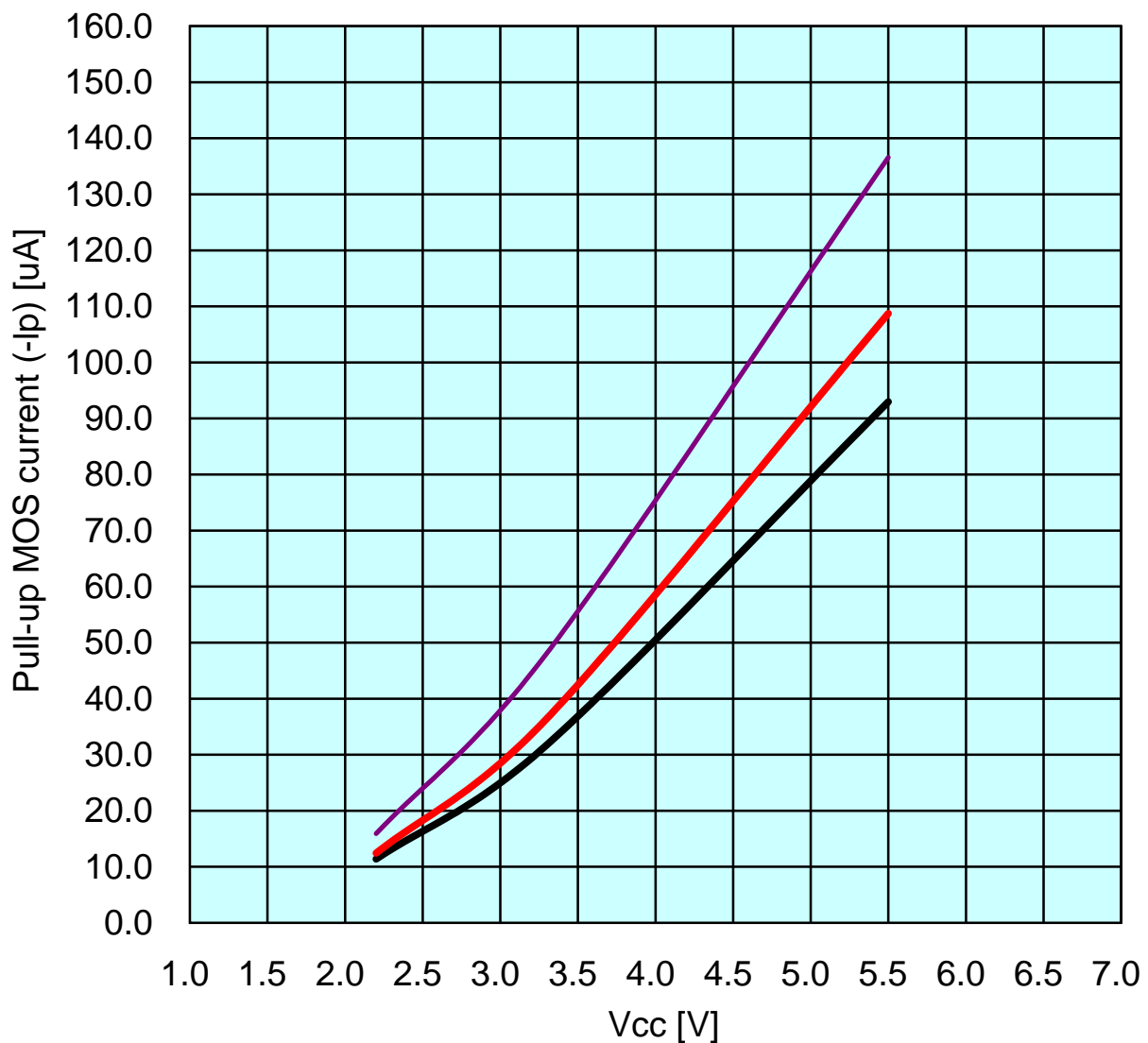

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.