


Icc vs Vcc (Low-speed clock mode)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
XIN clock off
High-speed on-chip oscillator off
Low-speed on-chip oscillator off
XCIN clock oscillator on = 32 kHz
FMR47 = 1

— 85degreesC
— -40degreesC

— 25degreesC

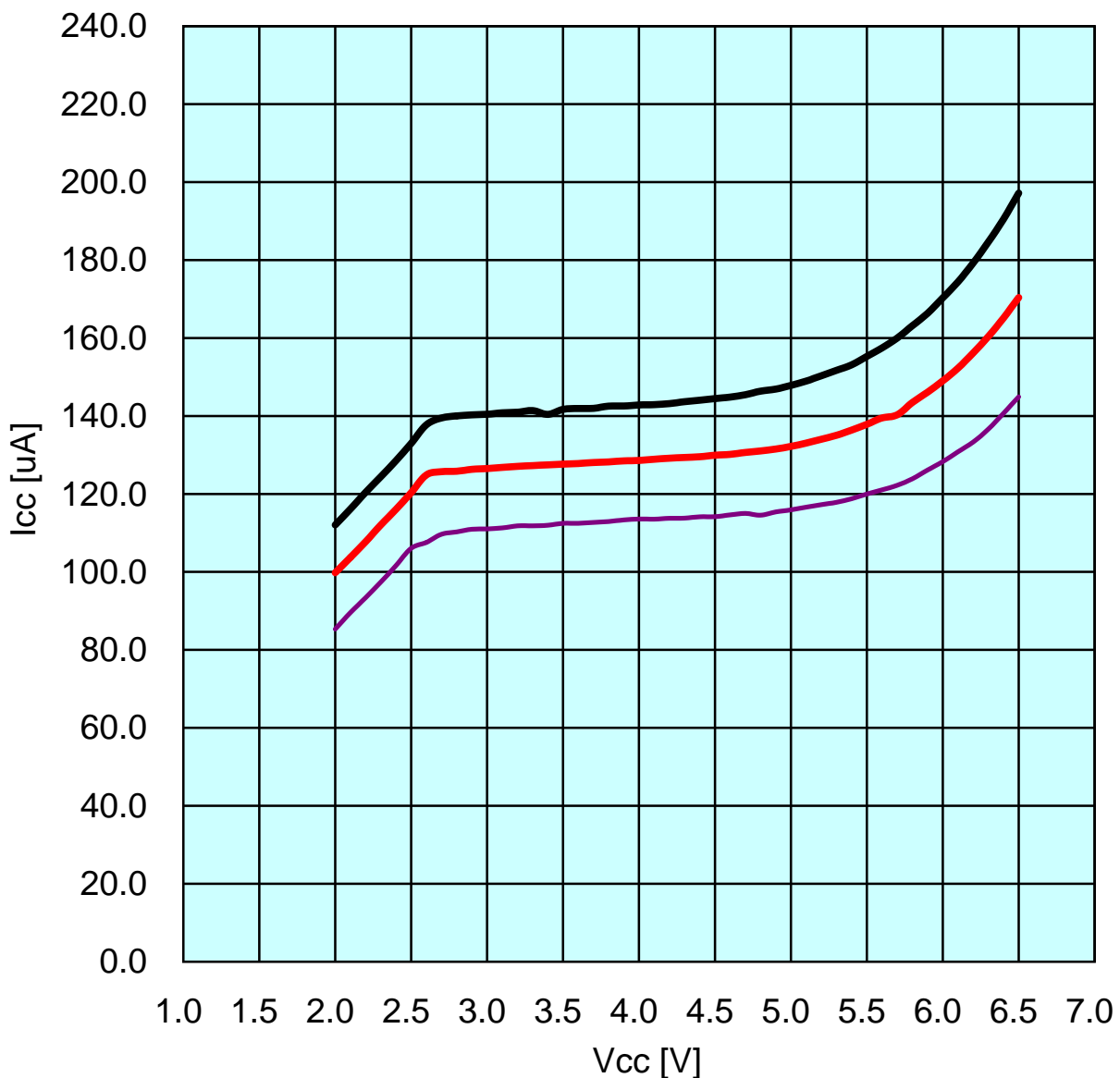

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.