

# IOH vs VOH (P2\_0-P2\_7 Drive Capacity=Low)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)

R5F21258SDFP(Topr=-40 to 85degrees C)


Topr=25degrees Celsius

Vcc=5V, 3V, 2.2V

— Vcc=5V

— Vcc=3V

— Vcc=2.2V

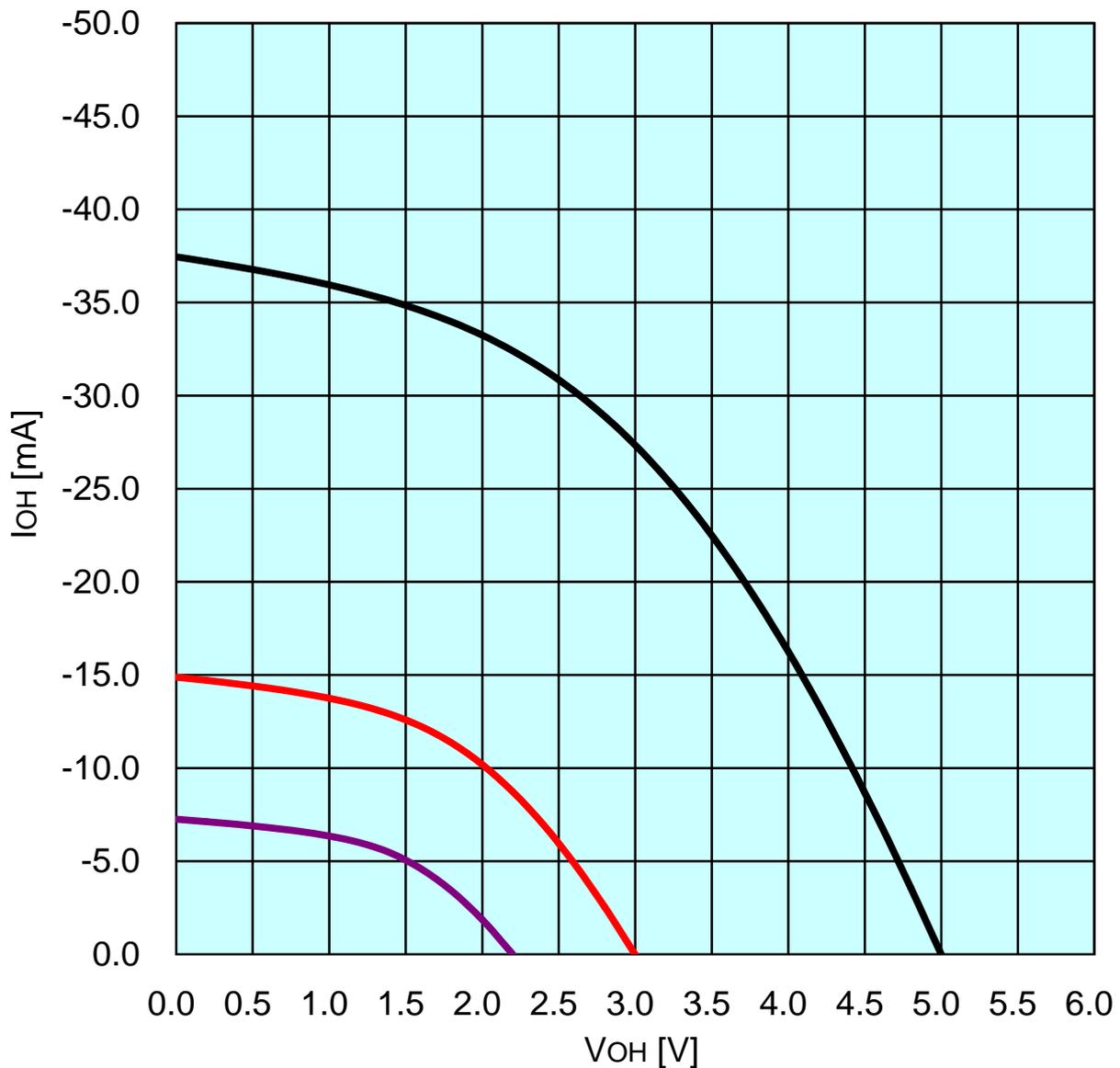

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.