


IOL vs VOL

(P2_0-P2_7 Drive Capacity=High)

Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)
R5F21258SDFP(Topr=-40 to 85degrees C)
Vcc=5V

— 85degreeC — 25degreeC
— -40degreeC

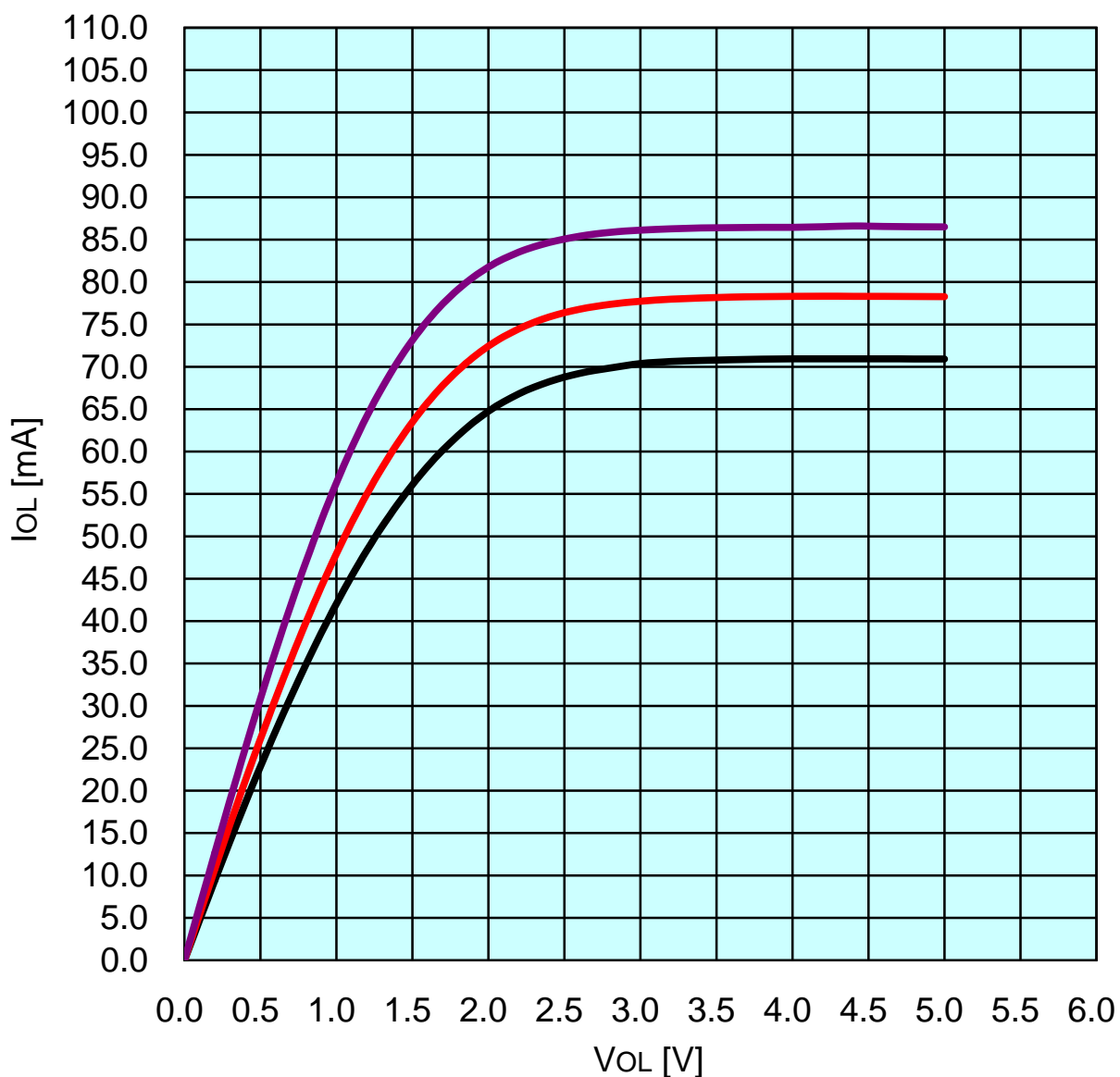

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.