

# VOL VS Vcc

(P0\_0-P0\_7,P1\_0-P1\_7,P3\_0,P3\_1,  
P3\_3-P3\_5,P3\_7,P4\_2-P4\_5,P6\_0-P6\_7)


Prepared on Oct. 20, 2006

R5F21258SNFP(Topr=-20 to 85degrees C)  
R5F21258SDFP(Topr=-40 to 85degrees C)  
Topr=25degrees C  
IOL=5mA, 1mA, 200uA

— IOL=5mA

— IOL=1mA

— IOL=200uA

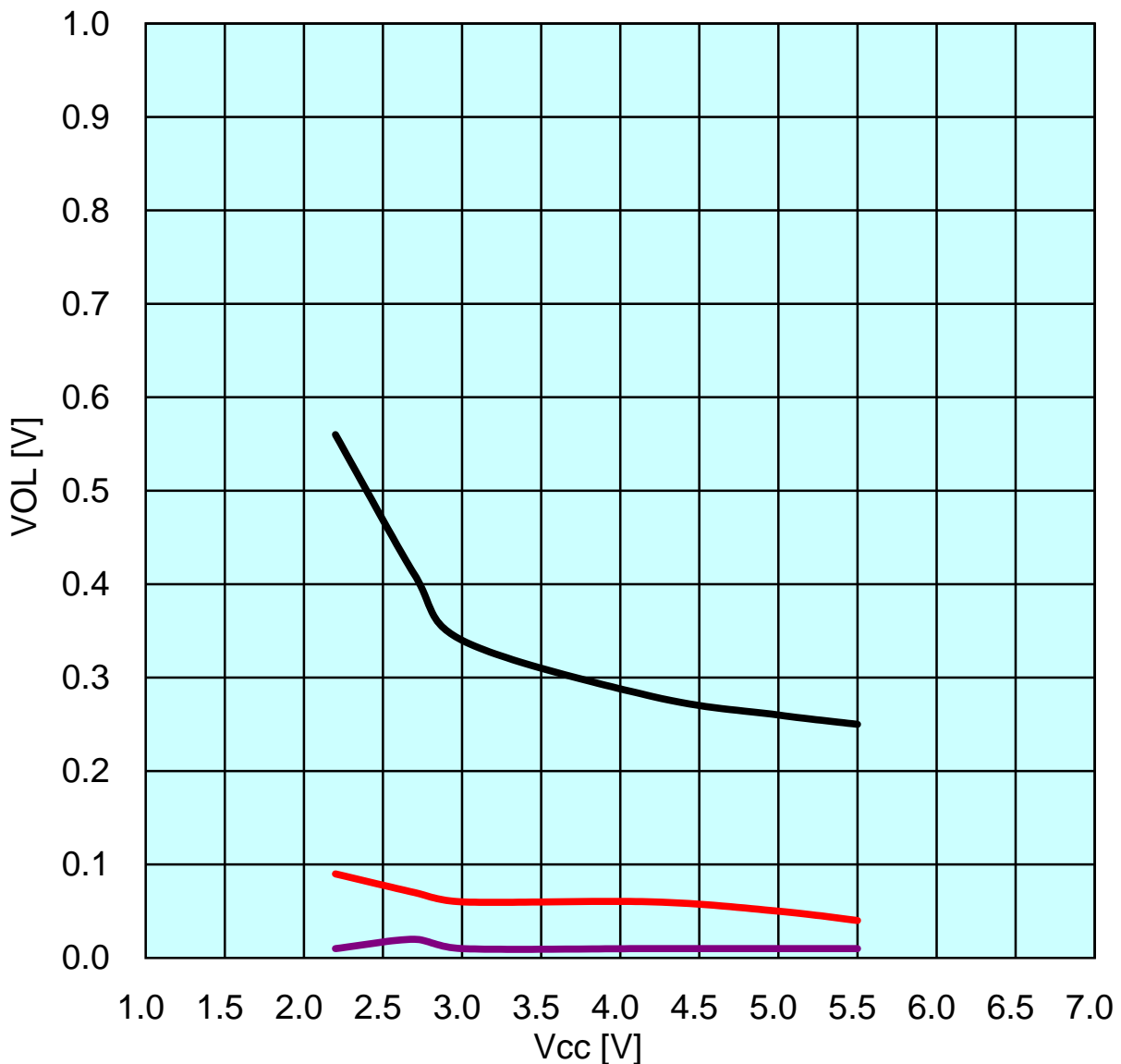

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.