

# VOH vs Vcc

(P0\_0-P0\_7, P3\_1, P3\_3-P3\_7, P4\_5, P5\_3, P5\_4)

Prepared on Sep. 10, 2007

R8C/26-27 Group


Topr = 25 degrees C

IOH = -5mA, -1mA, -200uA

— IOH = -5mA

— IOH = -1mA

— IOH = -200uA

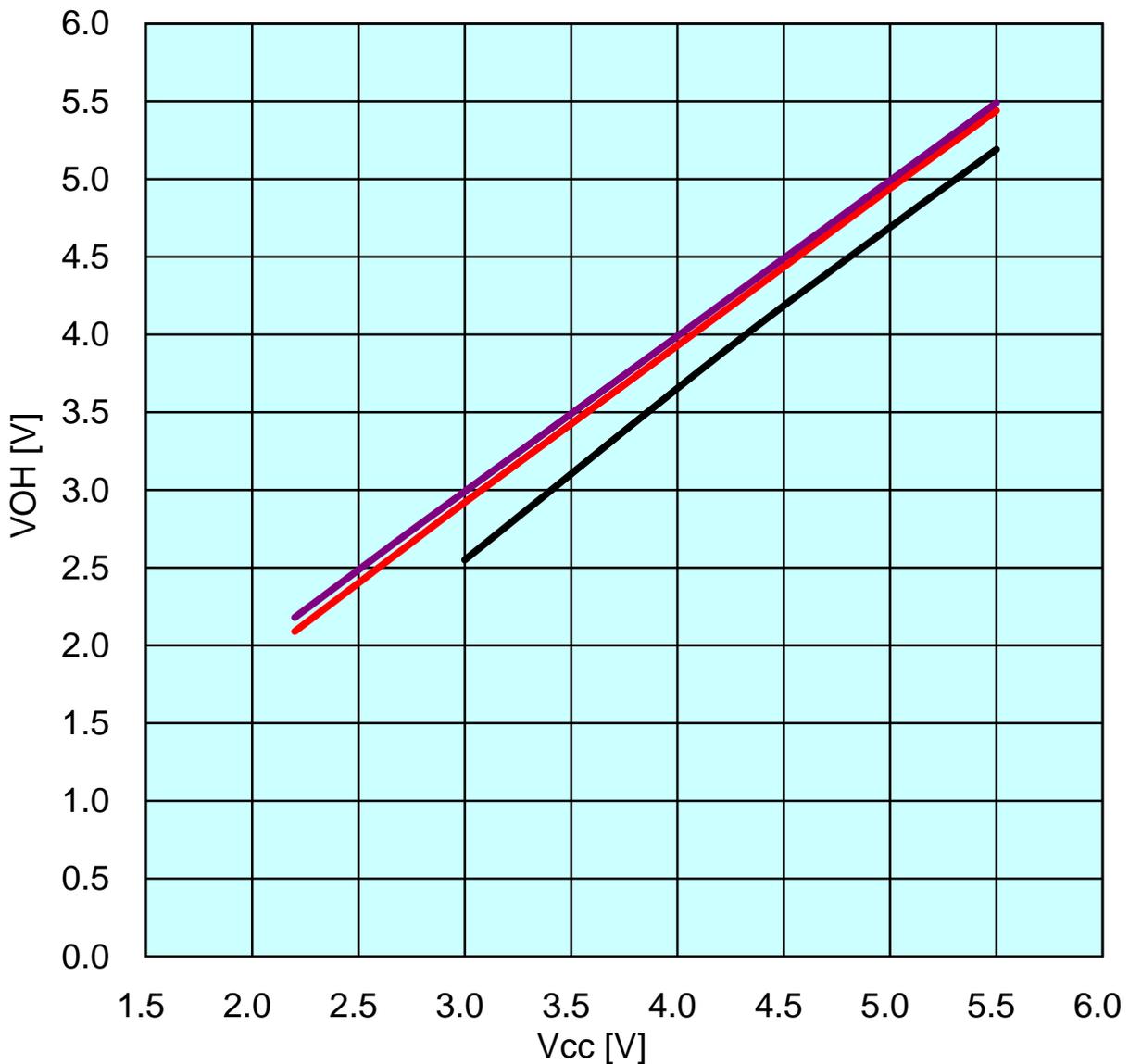

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.