

A/D accuracy 10bit

R8C/28-29 Group

Topr = -40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=5.120V

Xin=20MHz ϕ_{AD} =10MHz sample and hold=on Repeat mode

Absolute accuracy
-2.61LSB

Prepared on Sep. 07, 2007

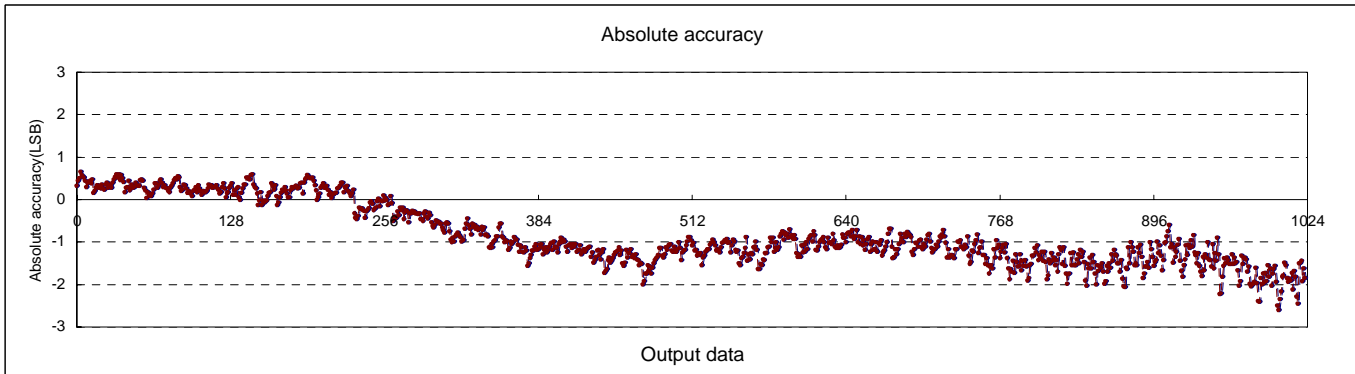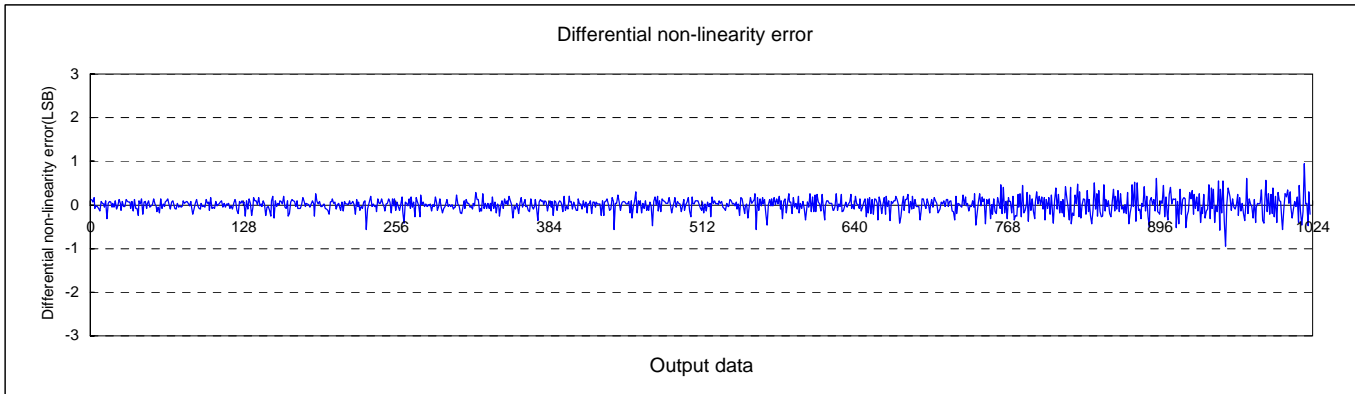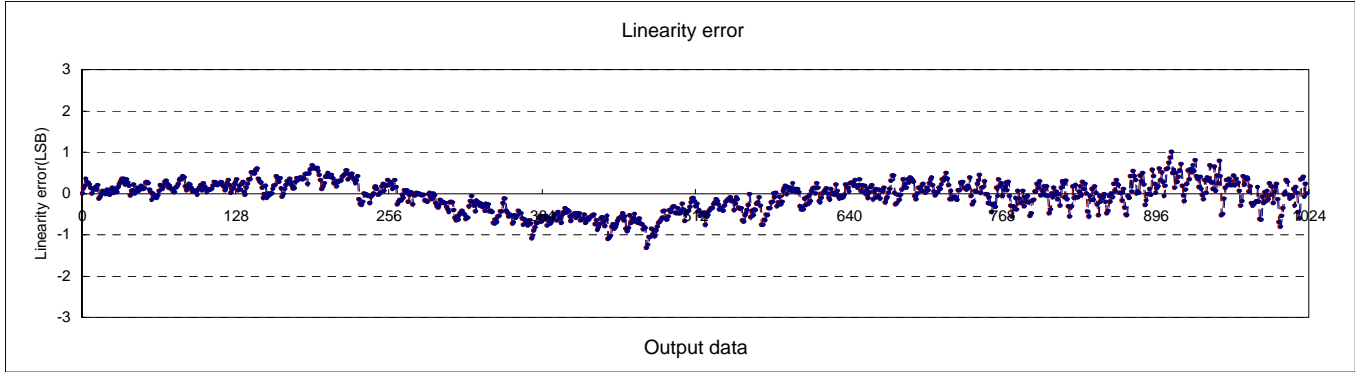

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.