


IOH VS VOH

(P0_0-P0_7,P1_0-P1_7,P3_0-P3_7,P4_3-P4_5,P5_0-P5_7,
P6_0-P6_7,P7_0-P7_7,P8_0-P8_7,P9_0-P9_3)

Prepared on Jul. 29, 2007

R8C/2A-2D Group
Vcc = 5.0V

— 85 degrees C — 25 degrees C
— -40 degrees C

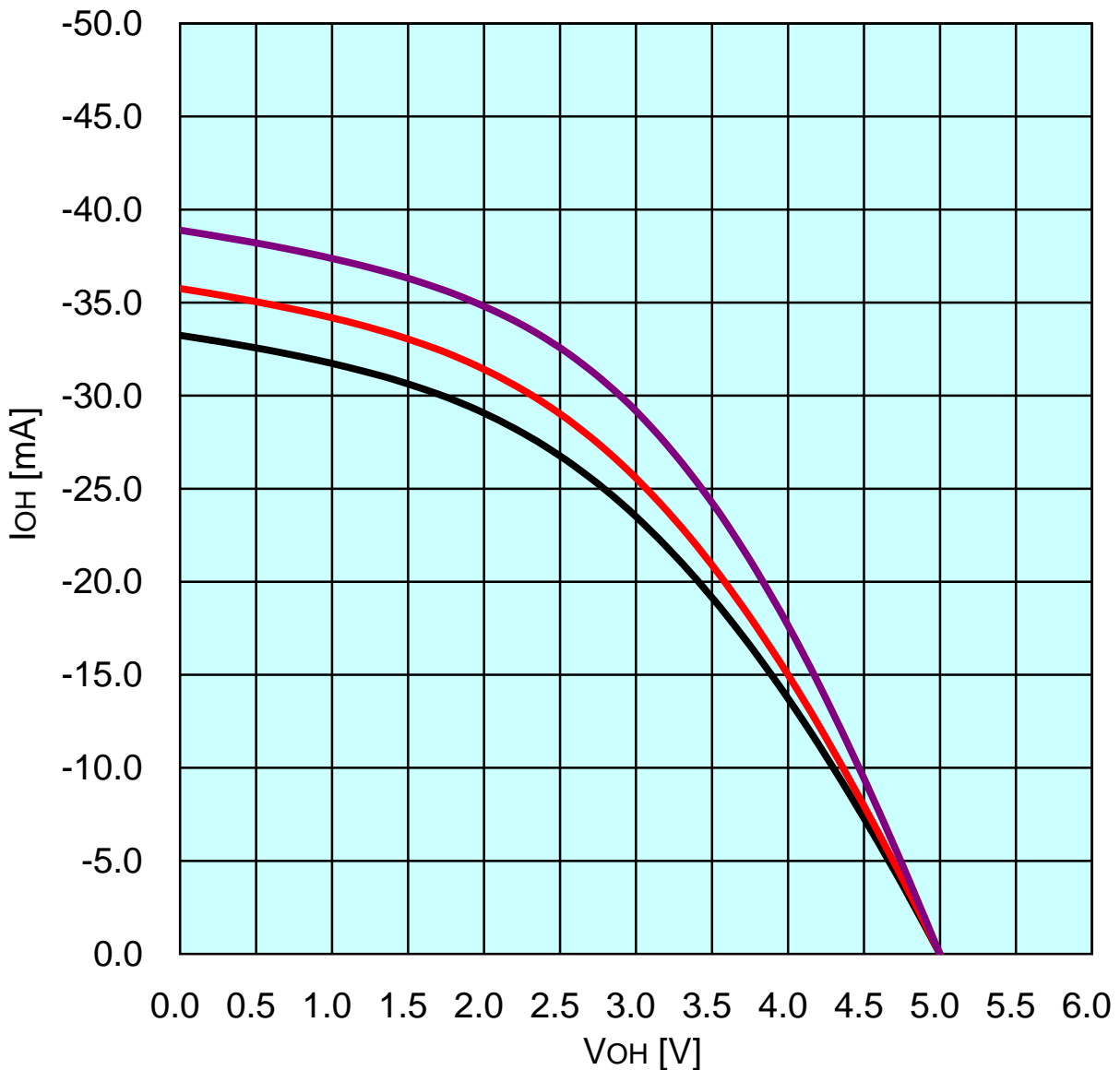

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.