

# VOH vs VCC

(P2\_0-P2\_7 Drive Capacity=High)

Prepared on Jul. 29, 2007

R8C/2A-2D Group


Topr = 25 degrees C

IOH = -20mA, -5mA, -2mA

— IOH = -20mA

— IOH = -5mA

— IOH = -2mA

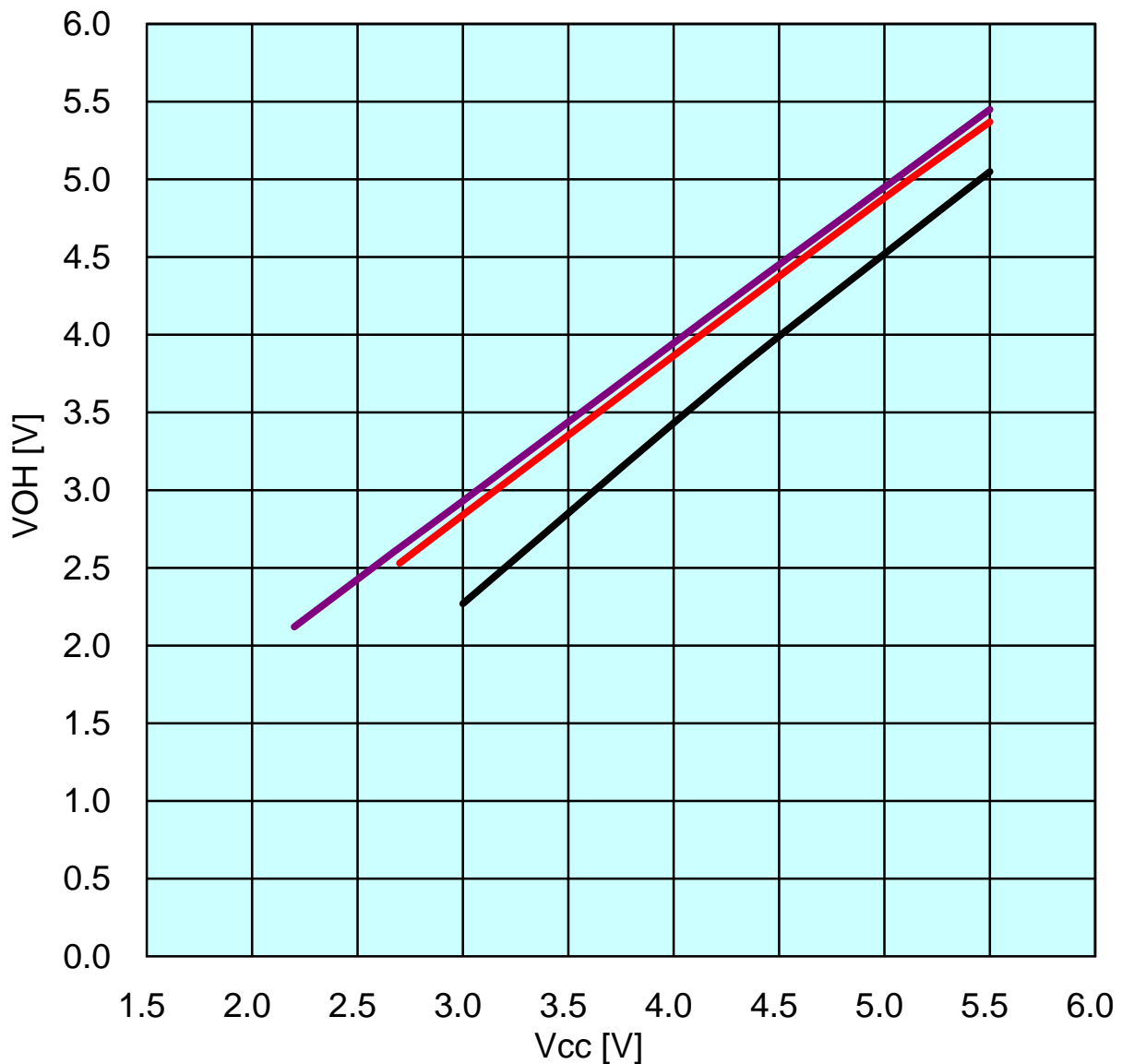

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.