


# Analog input current vs AVcc (AN2, AN4-AN11)

Prepared on Feb. 21, 2008

R8C/2K Group  
Topr=25 degrees C  
AVcc-Vss: 0.1uF Vref-Vss: 0.1uF  
ANIN-Vss: 0.1uF  
AVcc=Vref  
Xin=10MHz  $\phi_{AD}$ =5MHz  
sample and hold=on Repeat mode

— Analog input=0V  
— Analog input=AVCC

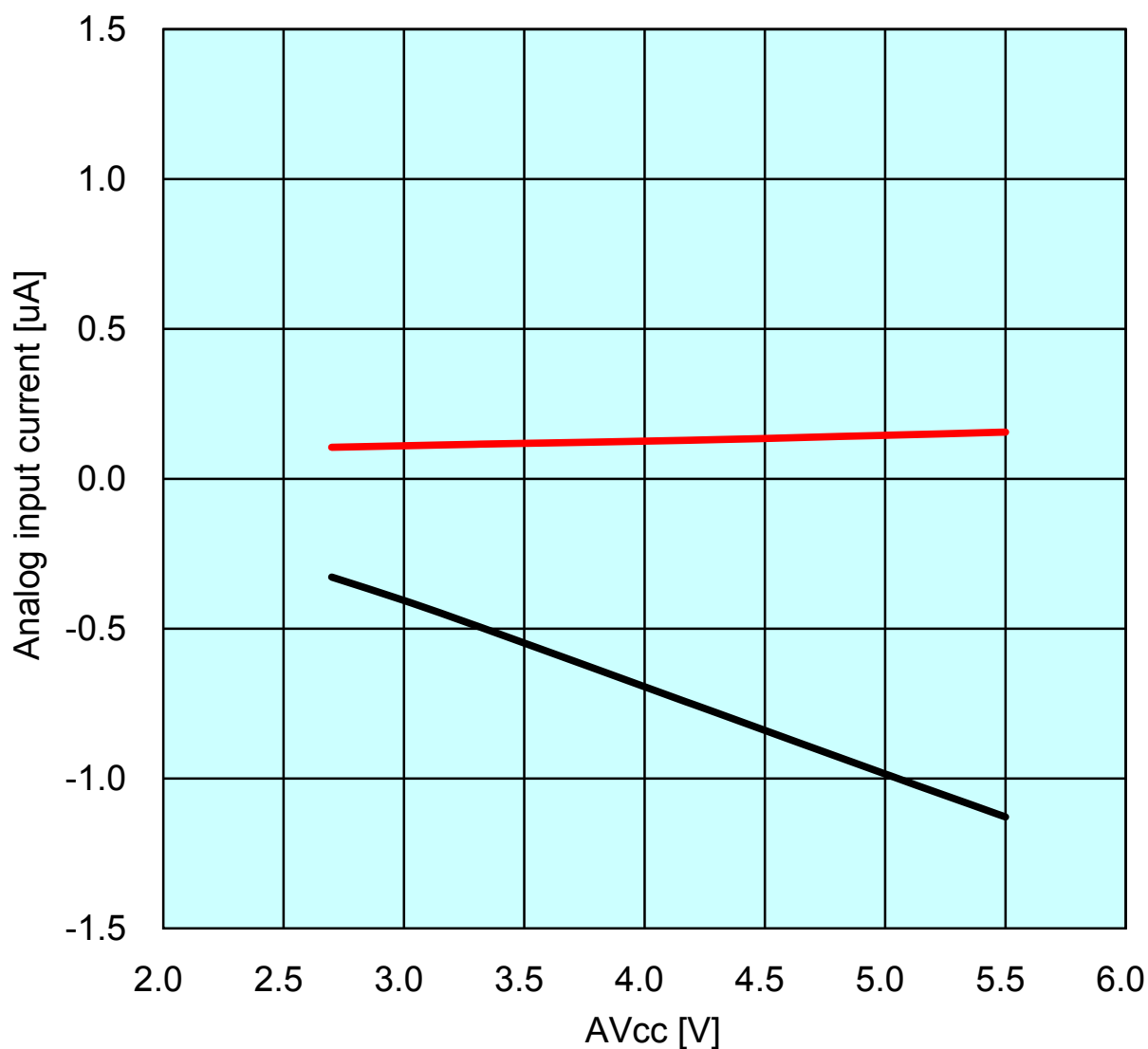

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.