

# A-D accuracy 10bit

Type: R8C/2K Group

Topr=-40 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=5.120V

Xin=20MHz  $\phi$ AD=10MHz sample and hold=on Repeat mode

Absolute accuracy  
-2.61LSB

Prepared on Feb. 21, 2008

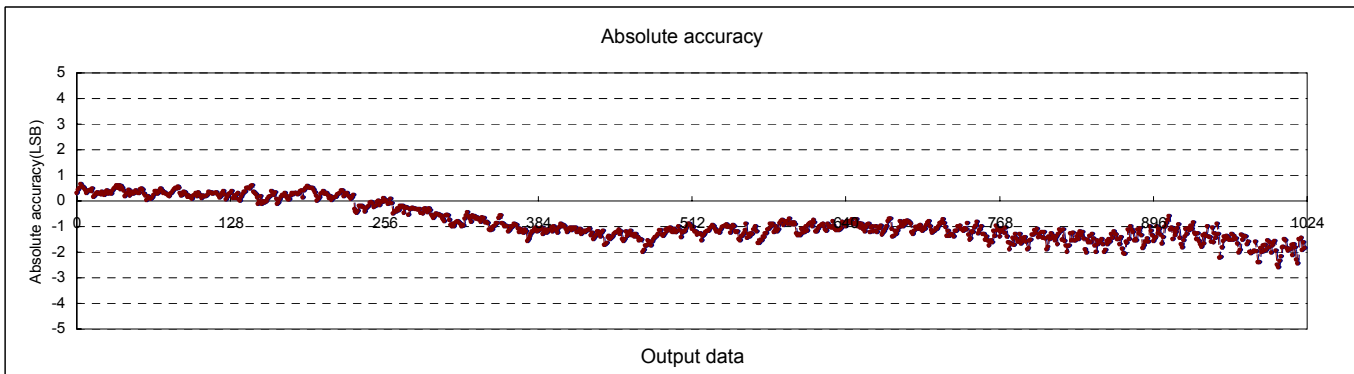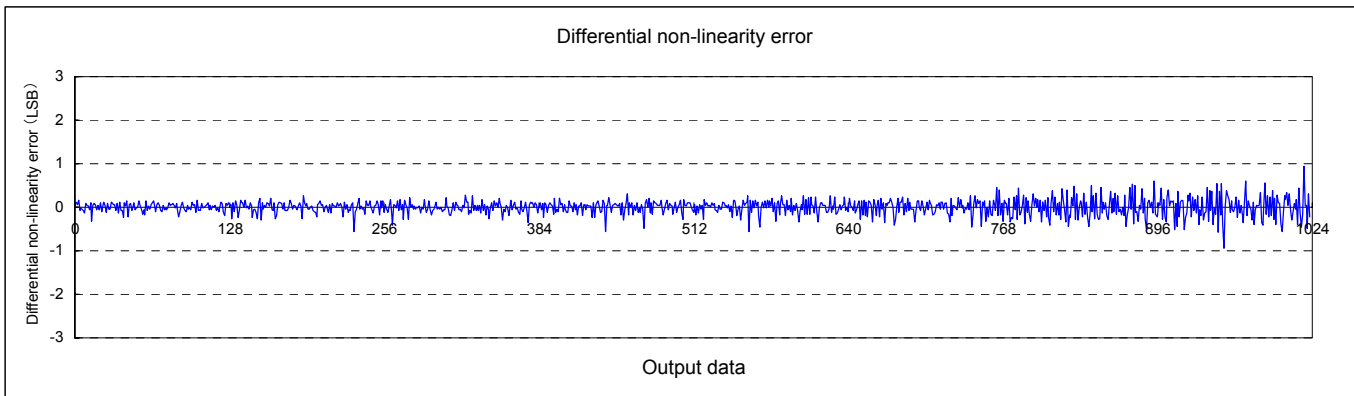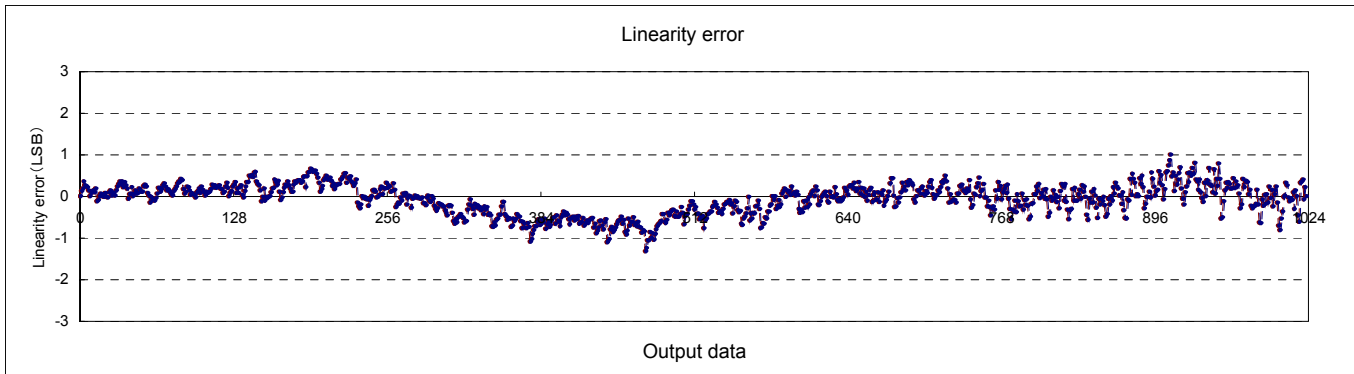

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.