

A-D accuracy 10bit

Type: R8C/2L Group

Topr=25 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=5.120V

Xin=20MHz φAD=10MHz sample and hold=on Repeat mode

Absolute accuracy
-1.81LSB

Prepared on Feb. 21, 2008

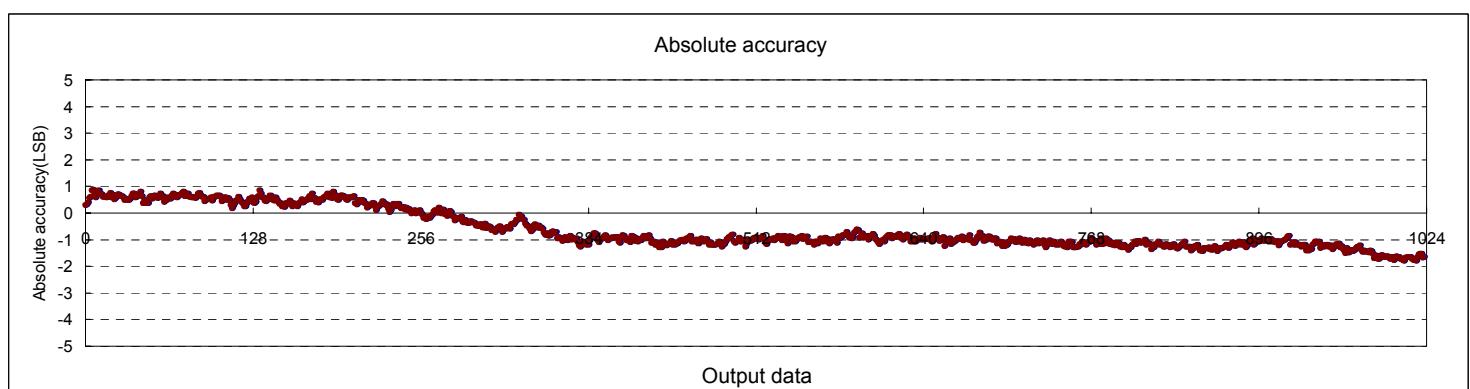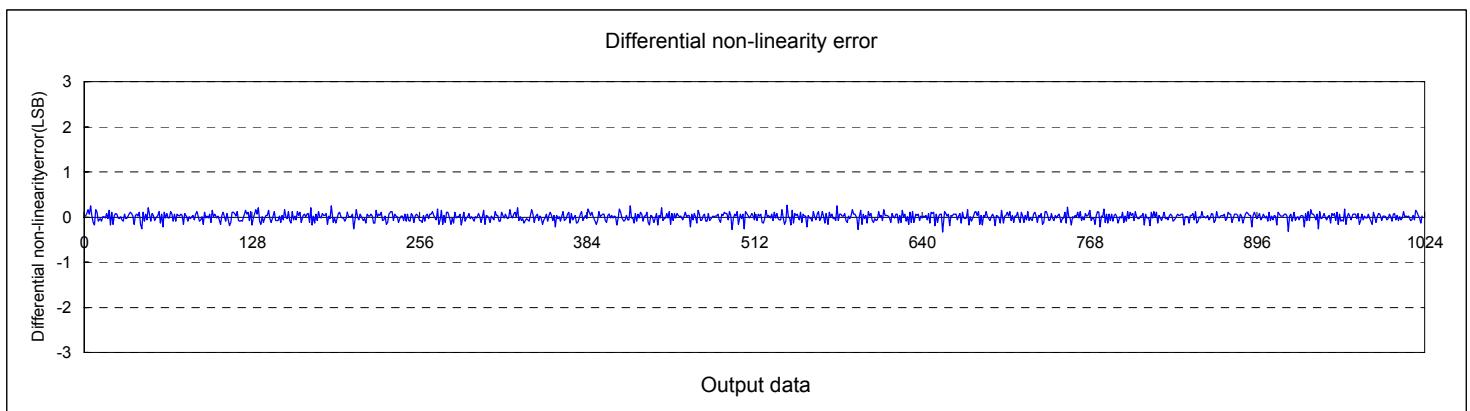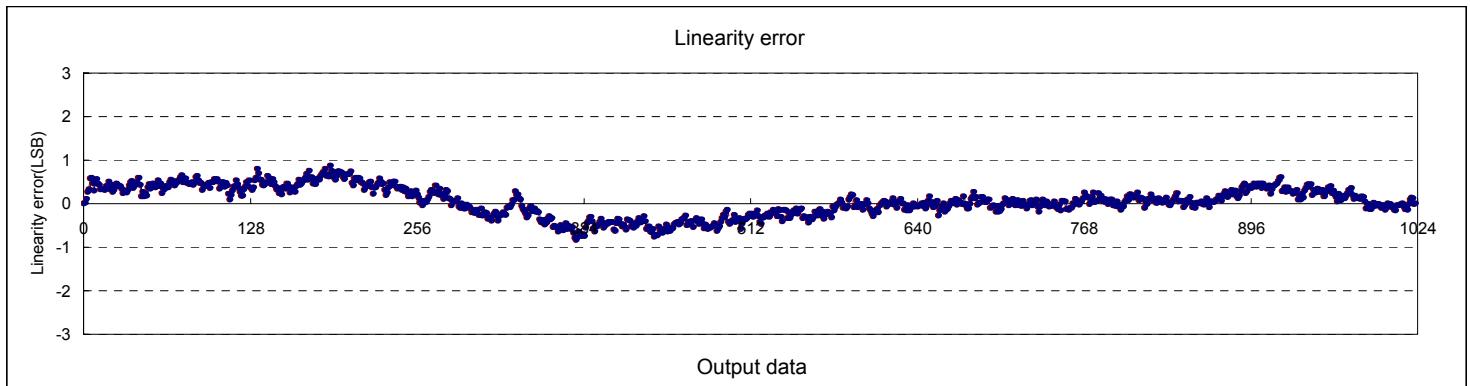

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.