

# A-D accuracy 10bit

Type: R8C/2L Group

Topr=25 degrees C




AVcc-Vss: 0.1uF Vref-Vss: 0.1uF ANIN-Vss: 0.1uF

AVcc=Vref=3.379V

Xin=20MHz  $\phi$ AD=10MHz sample and hold=on Repeat mode

Absolute accuracy  
1.81LSB

Prepared on Feb. 21, 2008

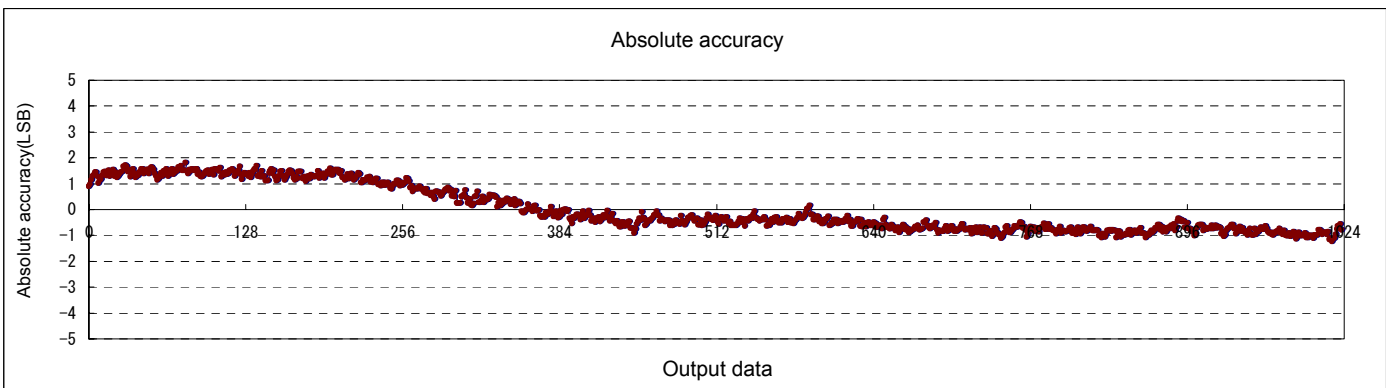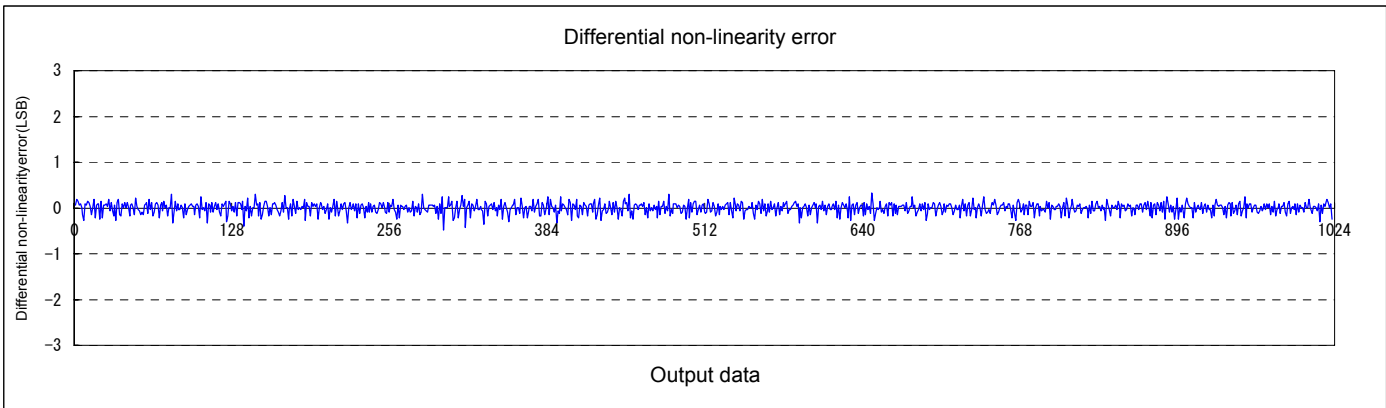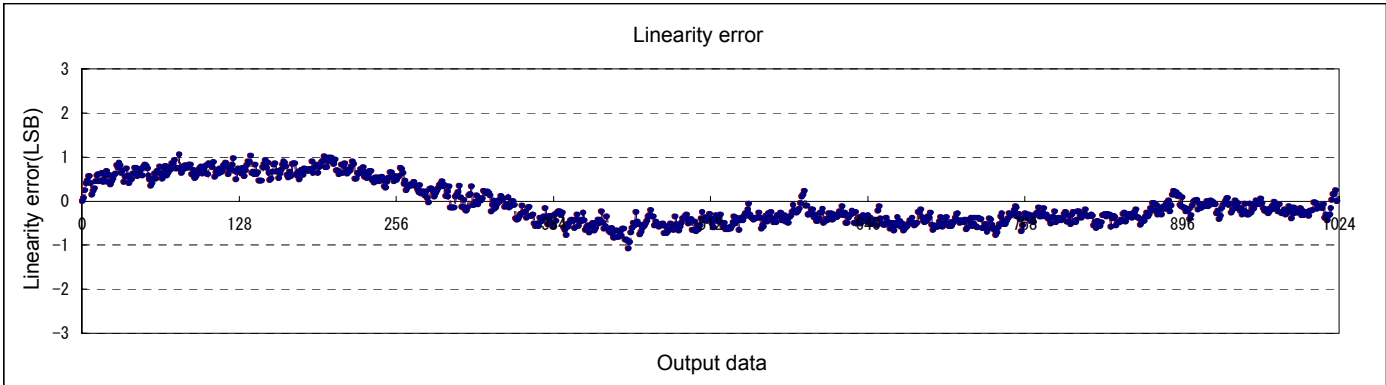

The mentioned value is only for your reference. The value is for the arbitrary samples and does not guarantee the product's characteristics.