
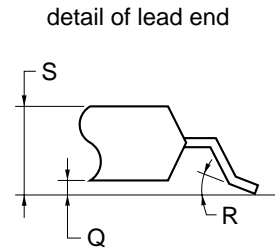


## 64-PIN PLASTIC QFP (14x14)

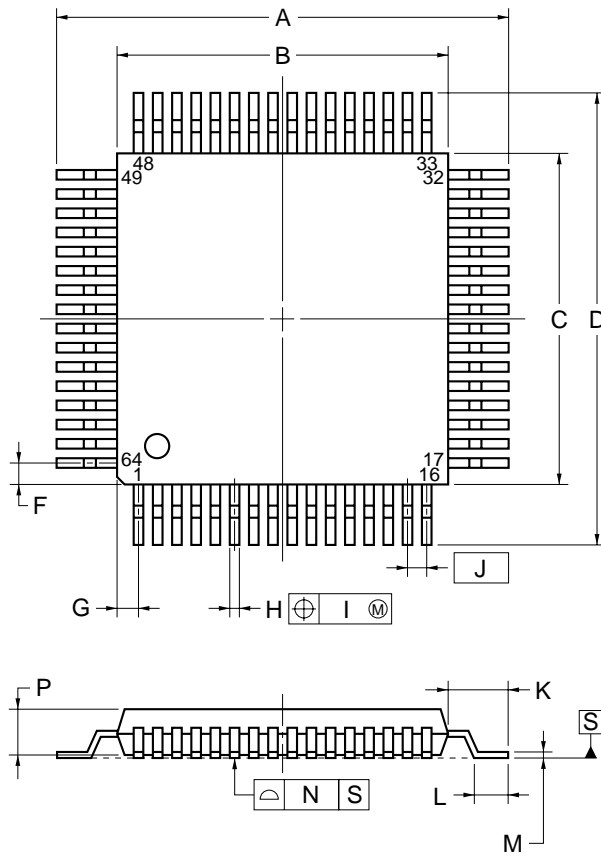

### NOTE

Each lead centerline is located within 0.13 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	17.2±0.2
B	14.0±0.2
C	14.0±0.2
D	17.2±0.2
F	1.0
G	1.0
H	0.35±0.10
I	0.13
J	0.8 (T.P.)
K	1.6±0.2
L	0.8±0.2
M	0.15 <sup>+0.10</sup> <sub>-0.05</sub>
N	0.10
P	2.7
Q	0.125±0.075
R	5°±5°
S	3.0 MAX.

S64GC-80-3BE-3