


30-PIN PLASTIC SDIP (10.16mm(400))

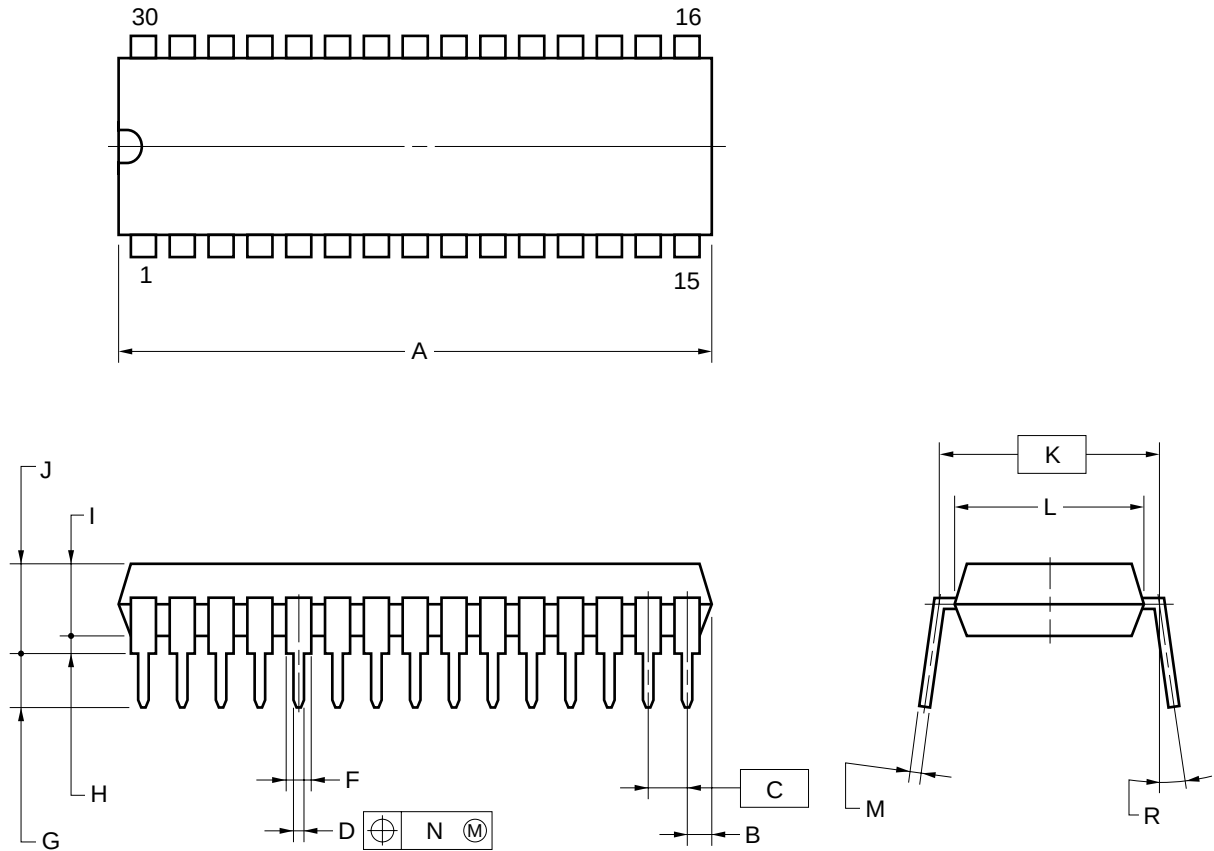

NOTES

- Each lead centerline is located within 0.17 mm of its true position (T.P.) at maximum material condition.
- Item "K" to center of leads when formed parallel.

ITEM	MILLIMETERS
A	27.3±0.2
B	1.78 MAX.
C	1.778 (T.P.)
D	0.50±0.10
F	1.0±0.15
G	3.2±0.3
H	0.51 MIN.
I	3.45±0.2
J	5.08 MAX.
K	10.16 (T.P.)
L	8.6±0.2
M	0.25 ^{+0.10} _{-0.05}
N	0.17
R	0~15°

S30C-70-400B-3